


Grundfos booster fast track

5-day despatch and 48-hour
shipment services



GRUNDFOS 

Possibility in every drop

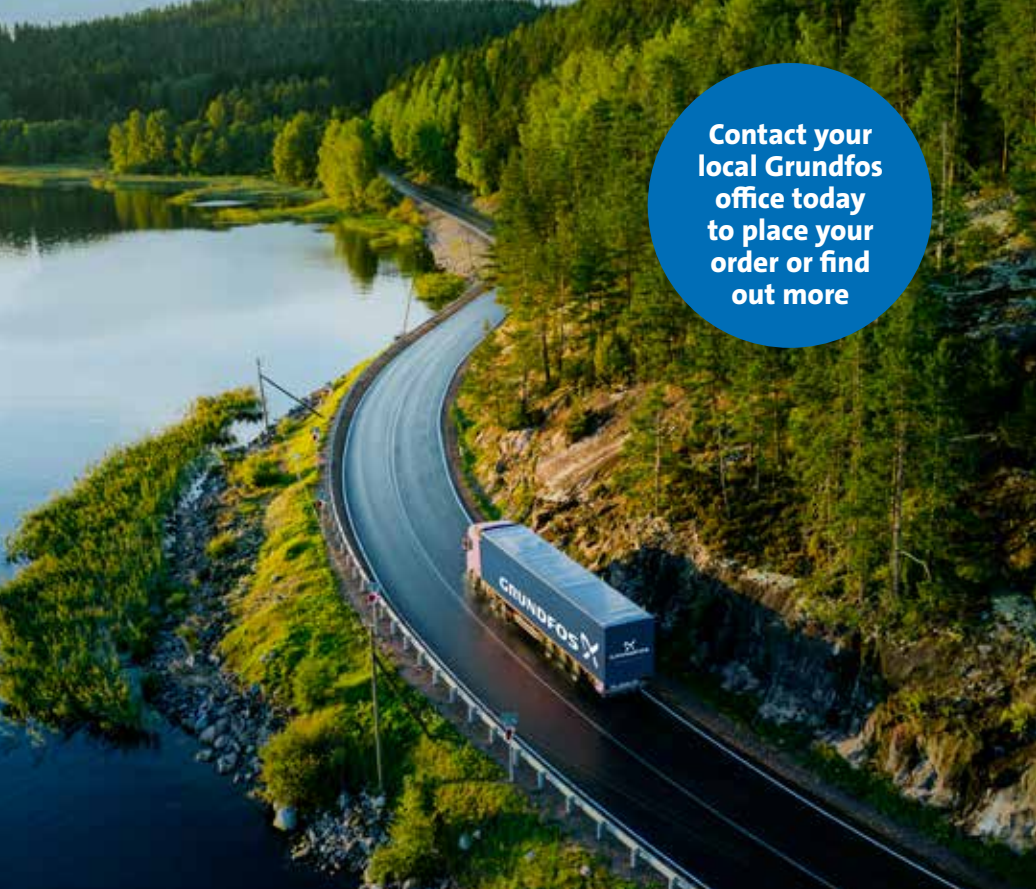

Contact your local Grundfos office today to place your order or find out more

5-day despatch on selected pressure boosters

Now you don't have to compromise between Grundfos quality and fast delivery, with our 5-day despatch on a selected range of pressure boosting options. What's more, if your desired model is already in stock, we'll even offer a premium 48-hour service!



Facts and features

Locally built with high grade materials, we've engineered our pressure boosters to deliver superior efficiency with advanced control options.



	Multi-E (CRIE)	Multi-E (CME)	MPC-E (CRIE)	SOLO-E	CMBE
Control modes					
Constant pressure	Default	Default	Default	Default	Default
Constant flow	●	●	●	●	●
Constant temperature	●	●	●	●	●
Proportional pressure	●	●	●	●	●
Commissioning					
Plug'n'Pump easy start-up	●	●	●	●	●
Additional feature setup via Grundfos GO handheld remote	●	●			●
Start-up wizard via integrated LCD screen			●	●	
Dimensions / layout					
Lowest footprint	●				
Lowest booster set height		●			●

Standard in all our fast track boosters:

- Easy commissioning
- Space-saving installation: no need for control cabinets
- Reduced noise level
- Dry run protection
- Soft fill feature
- Maximum energy efficiency: motors surpass IE5 benchmarks
- Multi-master system architecture
- Energy optimising pump cascade management
- Stainless steel (hygienic) construction
- Regulation compliant predefined pressure tank
- Standard suction sensing plus primary & redundant discharge sensors
- Communication upgrades possible (Grundfos CIM)

Booster fast track range



**HYDRO
MULTI-E**

Turnkey booster system with CRE, CRIE or CME pumps suitable for a wide range of light and intermediate commercial applications.

- Integral easy to use controls with large display
- Energy-optimised control
- 2-3 pumps in cascade
- Remote control via Grundfos GO app

Technical data

Flow rate: max. 140 m³/h

Head: max. 133 m

Liquid temperature: 0 to 60 °C

Operating pressure: max. 16 bar



HYDRO MPC-E

Turnkey booster system with CR, CRI, CRIE pumps and CU 352 controller suitable for transferring and pressure boosting in commercial building and water supply system applications.

- Large user-friendly display
- Energy-optimised control
- Data communication
- Perfect constant pressure

Technical data:

Flow: max. 1080 m³/h

Head: max. 155 m

Liquid temp: 0°C to +60°C

Max. system pressure: 16 bar



Scan the QR
codes to find full
specifications
and more
online



HYDRO SOLO-E

Single pump booster system with a single CRE pump suitable for applications such as apartment buildings, schools, hotels, office buildings, industrial water supply systems, water treatment systems, water filtration systems, small industries, and washing & cleaning systems.

- Perfect constant pressure
- Easy to control
- Data communication
- Remote control via Grundfos GO app

Technical data:

Flow rate: max. 70 m³/h
Head: max. 149 m
Liquid temperature: 0 to 70 °C
Operating pressure: max. 16 bar



CMBE

Single pump booster system with a single CME pump for domestic and light commercial applications such as apartment buildings, schools, small hotels & guest houses, and small office buildings.



- Constant pressure via integrated speed control
- Compact construction
- Low noise level, 55 dB(A)
- Remote control via Grundfos GO app

Technical data:

Flow rate: max. 16 m³/h
Head: max. 99 m
Liquid temperature: 0 to 60 °C
Operating pressure: max. 10 bar



Curves

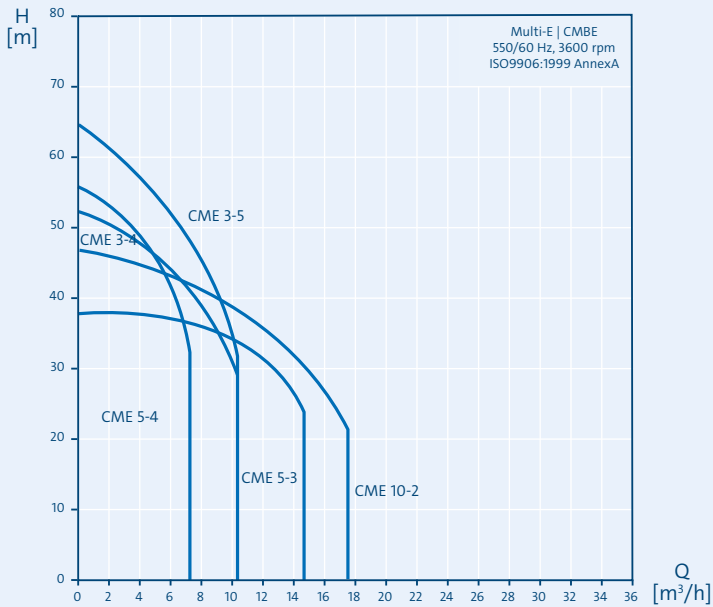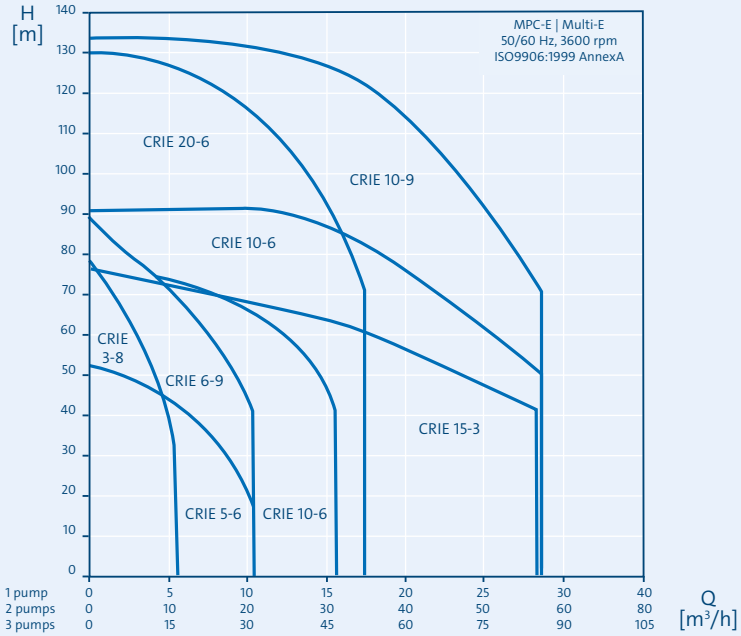

Product numbers

Our booster fast track 5-day despatch service is available for the following pressure boosters, with a premium 48-hour service subject to availability. For further details or to place your order, contact your local Grundfos office.

Product code	Number of pumps	Description
Hydro Multi E – CRE:		
98584969	2	CRIE 5-5
98486672	3	CRIE 3-8
98486720	2	CRIE 3-11
98486722	2	CRIE 5-5
98486730	3	CRIE 5-5
98486772	2	CRIE 5-9
98486777	3	CRIE5-9
99133119	3	CRIE10-5
Hydro Multi E – CME:		
98486648	2	CME3-5
98486695	2	CMES-4
98486751	2	CME10-2
Hydro MPC		
98426900	3	CRIE 3-8
98426914	2	CRIE 5-5
98426915	3	CRIE 5-5
98426917	2	CRIE 5-9
98426918	3	CRIE5-9
99257342	3	CRIE10-5
99208289	3	CRIE10-6
99208312	4	CRIE10-9
99257345	3	CRIE15-3
99257266	3	CRIE20-6
Max-E boost		
98536448	1	CRIE5-4
Hydro Micro E		
98784516	2	CME3-4
98784517	2	CME3-5
98784519	2	CME5-3
98784520	2	CME5-4

Grundfos Holding A/S
Poul Due Jensens Vej 7
DK-8850 Bjerringbro
Tel: +45 87 50 14 00
www.grundfos.com

GRUNDFOS 